
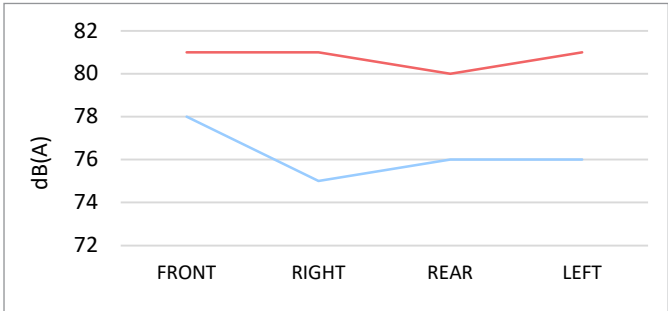


LEVEL 1 SOUND ATTENUATED ENCLOSURE D6.7L FPT, SD130

60Hz NO-LOAD, dB(A)											DISTANCE: 7 METERS
MICROPHONE LOCATION	OCTAVE BAND CENTER FREQUENCY (Hz)										
	31.5	63	125	250	500	1,000	2,000	4,000	8,000	dB(A)	
FRONT	35	51	63	69	73	73	67	64	56	78	
RIGHT	29	51	64	68	71	67	65	62	55	75	
REAR	32	54	66	70	72	68	62	60	52	76	
LEFT	30	52	65	67	73	70	65	62	54	76	
AVERAGE	32	52	64	68	72	69	65	62	54	76	

60Hz FULL-LOAD, dB(A)											DISTANCE: 7 METERS
MICROPHONE LOCATION	OCTAVE BAND CENTER FREQUENCY (Hz)										
	31.5	63	125	250	500	1,000	2,000	4,000	8,000	dB(A)	
FRONT	36	64	77	69	75	72	67	64	58	81	
RIGHT	35	65	79	68	72	68	65	63	55	81	
REAR	33	65	79	68	72	68	63	60	52	80	
LEFT	33	65	79	69	72	70	66	63	56	81	
AVERAGE	34	65	79	68	73	69	65	62	55	81	

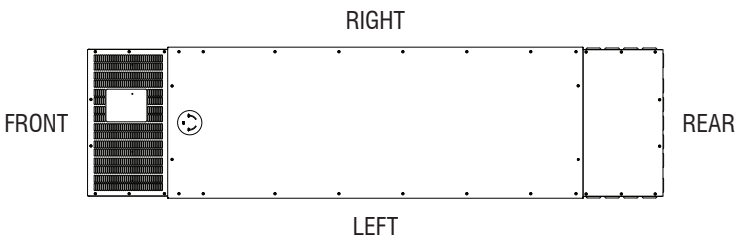

- All positions at 23 feet (7 meters) from side faces of generator set.
- Test conducted on a 100 foot diameter asphalt surface.
- Sound pressure levels are subject to instrumentation, installation and testing conditions.
- Sound levels are ± 2 dB(A).