

GP15000E

GP SERIES Commercial/Residential Portable Generators

1 of 2

Model 5734-1 UPC: 696471057348
(EPA/49-State)


Features

- The **Generac OHVI® engine** incorporates full pressure lubrication with automotive style spin on oil filter for longer life engine.
- **Low-oil pressure shutdown** automatically safeguards engine from damage.
- **Large-capacity fuel tank** with incorporated fuel gauge provides durability and extended run times.
- **Hardened 1 1/4" steel tube cradle** for added strength and durability.
- **Hour Meter** tracks maintenance intervals.
- **Heavy-duty, pneumatic wheels** for reliable portability.
- **Electric Start**, battery included, provides hassle-free start-up.
- **Idle control** reduces noise and conserves fuel for extended run-times.
- **Integrated lifting eye** for easy transport and security on the job site.



AC Rated Output Running Watts 15000
AC Maximum Output Starting Watts 22500

49-State Control Panel

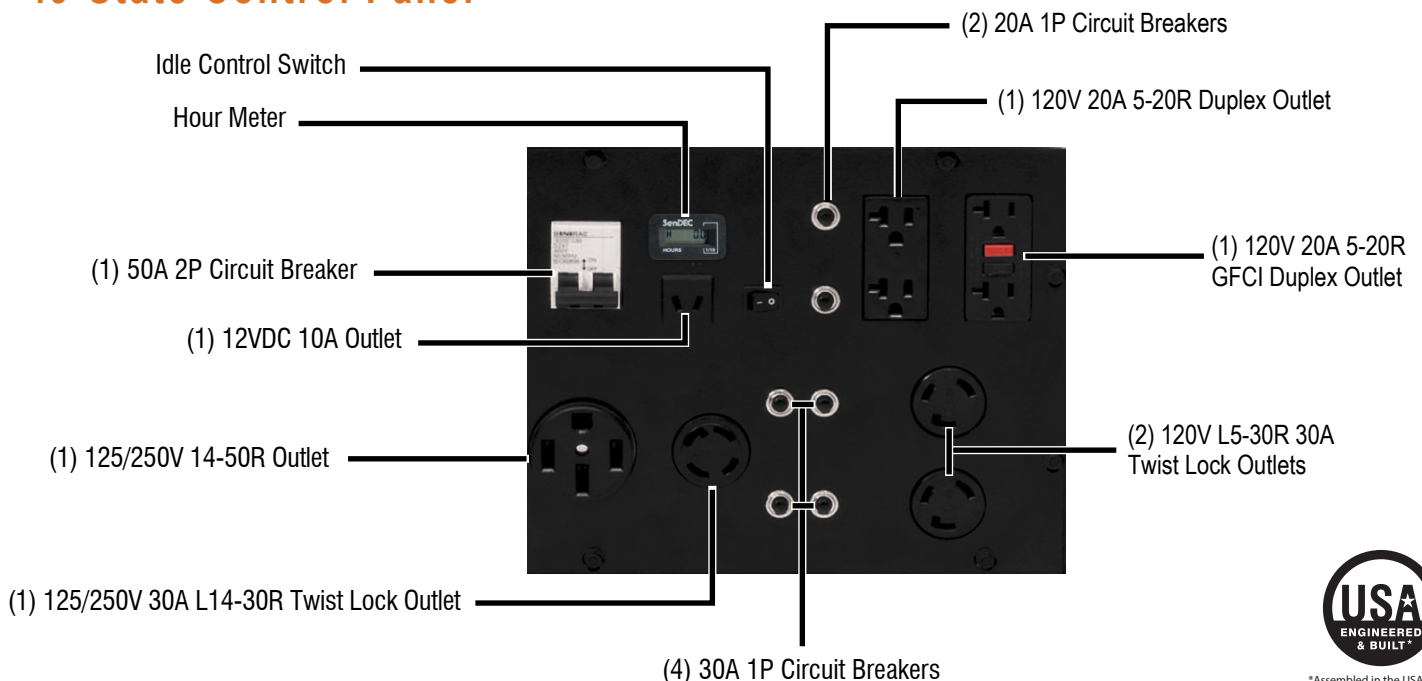

*Assembled in the USA using domestic and foreign parts

GP15000E

Specifications

| | |
|--|---|
| Product Series | GP15000E |
| Model (Configuration) | 5734-1 (EPA/49-State) |
| AC Rated Output Running Watts | 15000 |
| AC Maximum Output Motor Starting Watts | 22500 |
| Rated AC Voltage | 120/240 VAC |
| Rated AC Frequency | 60 Hz |
| Rated VAC Amperage | 125/62.5 |
| Max Rated VAC Amperage | 187.8/93.75 |
| Engine Displacement | 992cc |
| Engine Type | OHVI |
| Engine RPM | 3600 |
| Recommended Oil | 10W-30 / SAE30 |
| Oil Capacity qt (L) | w/ Filter Change: 1.7 (1.6) w/o Filter Change: 1.4 (1.3) |
| Lubrication Method | Oil Pump |
| Automatic Voltage Regulation (AVR) | Yes |
| Oil Filter | Yes - Spin On |
| Choke Location | On Engine |
| Fuel Shut Off | On Fuel Tank |
| Starting Method | Electric |
| Low Oil Shutdown Method | Low Pressure |

| | |
|-------------------------------|-----------------------------------|
| Battery Included | Yes |
| Battery Type | Group U1 |
| Battery Part No. | Purchase Locally |
| Battery Dimensions | Group U1 has a standard case size |
| Neutral Bonded to Ground | No - Floating Neutral |
| Start Switch Type | On/Off/Start Switch |
| Switch Location | On Engine |
| Fuel Gauge | Built-In Tank |
| Fuel Tank Capacity Gal (Ltrs) | 16 (60.6) |
| Fuel Filter | Yes |
| Run Time at 50% (Hours) | 10 |
| Handle Style | Fixed |
| Wheel Type | 12.3 Pneumatic Wheels |
| Warranty- Residential | 2 Year Limited |
| Warranty- Commercial | 1 Year Limited |

Maintenance Kit

Included - Model 5721
Air Filter
Oil Filter
(2) Spark Plugs
Oil Funnel
Chamois
Stabil Sample

Dimensions and Weights

| | |
|--------------------------|-------------|
| Length in (mm) | 48.5 (1232) |
| Width in (mm) | 31 (787) |
| Height in (mm) | 39.5 (1003) |
| Carton Length in (mm) | 49 (1245) |
| Carton Width in (mm) | 23.25 (592) |
| Carton Height in (mm) | 35.5 (902) |
| Unit Weight lbs (kg) | 363 (165) |
| Shipping Weight lbs (kg) | 425 (193) |

